

WHY CHOOSE REX® AND LINK-BELT® MOUNTED ROLLER BEARINGS?

RANGE OF OPTIONS

Rex and Link-Belt roller bearings offer the best range of performance options based on your application needs. From seal types to bore diameters to shaft locking options, no one offers more choices than Regal Rexnord. The result is a bearing family that delivers the best value on choice, delivery and life.

SOLID HOUSING

Our spherical roller bearings offer a range of solid housings that utilize the industry's only two-piece outer ring, interchangeable seals, larger rollers and in-field clearance setting capabilities. The rugged, one-piece housing arrives pre-loaded with lubricant, which decreases installation time and increases bearing life.

CUSTOM APPLICATIONS


The unique modular design of the Rex and Link-Belt roller bearings allow for assembled-to-order configurations. Our Application Engineers offer deep technical and functional knowledge to provide customers with predictive bearing performance analysis so the right product is selected for each application.

RUGGED PERFORMER

Rex and Link-Belt products are proven performers in the industry and represent the quality and value our customers have come to expect from a leader. Regal Rexnord roller bearings have higher thrust load carrying capacity than any comparable product in the market.

AVAILABILITY

We understand that equipment downtime is not an option for our customers. Regal Rexnord utilizes a network of warehouses and distribution channels to provide inventory coverage for our product offering and provide greater customer satisfaction.

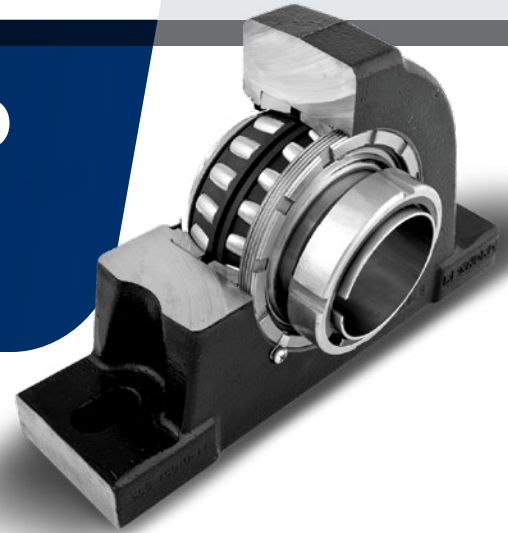

Industries Served:

- Aggregates
- Air Handling
- Construction Machinery
- Food & Beverage
- Forest Products
- Material Handling
- Mining
- Pumps & Compressors
- Heavy Duty Truck
- Steel



WHY CHOOSE REX® AND LINK-BELT® MOUNTED ROLLER BEARINGS?



**Rex®
Z Seal**
Non-Contact Seal



**Rex
K Seal**
Light Contact Seal



**Rex
M Seal**
Heavy Contact Seal



**Rex
G Seal**
Triple Lip Seal



**Link-Belt®
H Seal**
Clearance Seal



**Link-Belt
E Seal**
Heavy Contact Seal



**Link-Belt
E7 Seal**
Triple Lip Seal

REX & LINK-BELT ROLLER BEARINGS

- Shaft sizes from 3/4" to 7"
- Full range of housing styles
- Multiple mounting options
- Self-aligning spherical roller bearing provides 4 degrees of misalignment
- Adjustable internal clearances
- Best-in-class load ratings
- Interchangeable seals

Roller elements machined to best-in-class tolerance provide longer bearing life


Super-finished raceways provide a cool running, quiet, high-speed & high-load capacity bearing

Cage options reduce noise and improve lubrication with polymeric or steel for high heat and shock loading

Field-interchangeable seal options to fit diverse applications

Positive locking system provides easy installation, even for undersized shafts

Solid housing reduces installation time and ships pre-loaded with the right lubricant for the application

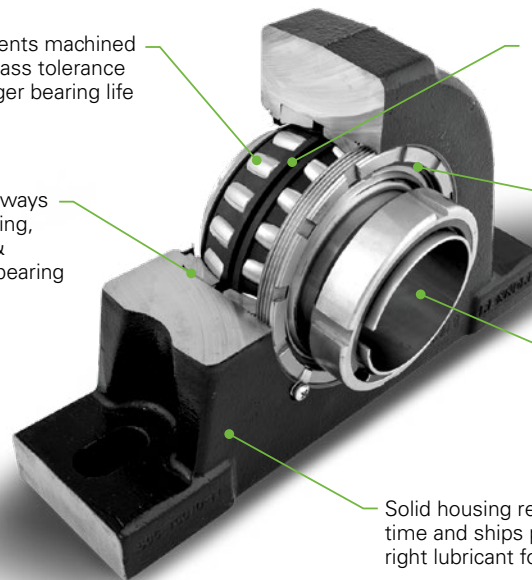

Rex® Link-Belt®

**Motion Control Solutions
Regal Rexnord**

Contact us: rexnord.com/contact

regalrexnord.com

The proper selection and application of products and components, including assuring that the product is safe for its intended use, are the responsibility of the customer. To view our Application Considerations, please visit <https://www.regalrexnord.com/Application-Considerations>. To view our Standard Terms and Conditions of Sale, please visit <https://www.regalrexnord.com/Terms-and-Conditions-of-Sale> (which may redirect to other website locations based on product family).

"Regal Rexnord" is not indicative of legal entity. Refer to product purchase documentation for the applicable legal entity. Regal Rexnord, Rex and Link-Belt are trademarks of Regal Rexnord Corporation or one of its affiliated companies. © 2012, 2023 Regal Rexnord Corporation, All Rights Reserved. MCSSP23025E • Form# BR5-011E

RegalRexnord™